




Featured Products Bulletin

POWER RESISTORS

Bourns Releases New Power Resistor Series

Riverside, California - April 9, 2007 - Bourns® Specialty Resistor Product Line introduces [Models PWR1913, PWR2615, PWR4525 and PWR6327](#). These parts are surface mount wirewound resistors with a power rating ranging from 0.5 to 3.0 W as well as a wide resistance range (0.01 to 25K ohms), excellent TCR (± 20 PPM) and a maximum operating temperature of 275° C.

These resistors are used in power supply circuits on boards for a wide range of computing, white goods, telecom and automotive applications for functions as diverse as current sensing in low ohmic values, active component biasing or as snubber resistors.

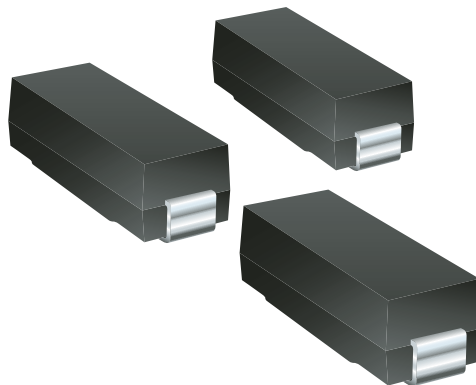

Features

- Surface mount wirewound resistor
- High power
- Low temperature coefficient
- RoHS compliant*
- Non-inductive versions available

Applications

- Power supplies
- Motor drives
- Electricity metering