

Features

- Dual and single through-hole models available
- Low height of only 6.3 mm
- Matched to leading transceiver ICs
- RoHS compliant*

Applications

- Telecom

PT66005L - ISDN S-Interface Transformer

Electrical Specifications @ 25 °C

Turns Ratio $\pm 5\%$ (I : II)	1:1
OCL (mH min.)	1.2
Interwinding Capacitance	
C _{ww} (pF max.).....	25
Leakage Inductance L _s (μ H max.)	0.5
HIPOT 50 Hz for 2 sec. (I : II).....	1500
DCR (Ω max.).....	0.7
Operating Temperature (°C).....	0 to +70

Other OCL specifications available on request.

Packaging Specifications

Tube 56 pcs./tube


How To Order

Model _____ **PT66005 L**




Termination _____

L = Tin only (RoHS Compliant)

Electrical Schematic

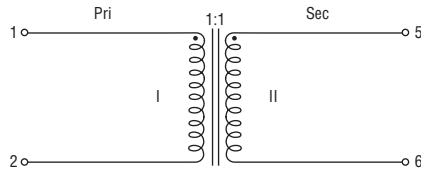

Product Dimensions

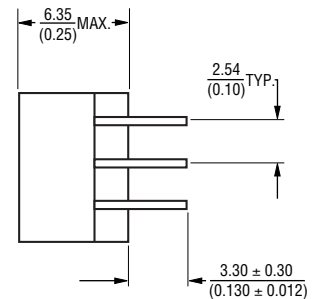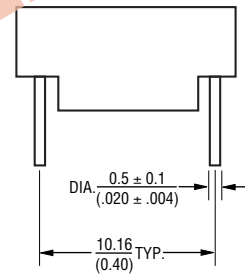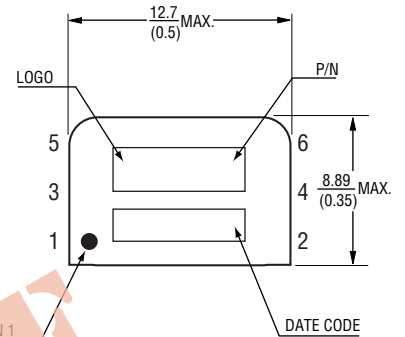

DIMENSIONS: $\frac{\text{MM}}{\text{(INCHES)}}$

OBSOLETE