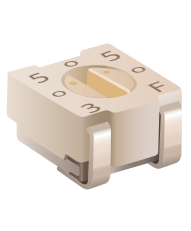


3313 Surface Mount AEC-Q200 Qualified 3 mm Single-turn Trimpot® Trimming Potentiometer

3313	Pin Style	Product Indicator	Resistance Range	Packaging
	J, X, S	1 = Standard Single Slot (Available in all pin styles) 2 = Standard Cross Slot (Available in all pin styles) GK2 = Custom Halogen Free Single Slot (Available in all pin styles) GL5 = Custom Halogen Free Cross Slot (Available only in J pin style) X = Reverse Pin Layout, Top Adjust S = Side Adjust J = J-Hook, Top Adjust	100 Ohms to 2 Megohms	E = 7" Reel J and X pin styles = 1000 pcs. S pin style = 200 pcs.

Part Number Examples


Model	Pin Style	Product Indicator	Resistance (Ohms)	Number of Pieces	Reel Size (Inches)
3313J-1-502E	J = J-Hook, Top Adjust	Single Slot (-1)	5000	1000	7
3313X-1-100E	X = Reverse Pin Layout, Top Adjust	Single Slot (-1)	10	1000	7
3313S-1-103E	S = Side Adjust	Single Slot (-1)	10000	200	7
3313J-GK2-105E	J = J-Hook, Top Adjust	Single Slot Halogen Free (-GK2)	1000000	1000	7

Standard Resistance Table

Resistance (Ohms)	Resistance Code
10	100
20	200
50	500
100	101
200	201
500	501
1,000	102
2,000	202
5,000	502
10,000	103
20,000	203
50,000	503
100,000	104
200,000	204
250,000	254
500,000	504
1,000,000	105
2,000,000	205

Popular distribution values listed in boldface. Special resistances available.

3314 Surface Mount AEC-Q200 Qualified 4 mm Single-turn Trimpot® Trimming Potentiometer

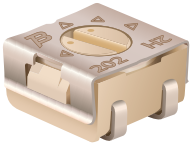3314	Pin Style	Product Indicator	Resistance Range	Packaging
	J, G, H, R, S, Z	<p>1 = Standard Single Slot (Available in all pin styles) 2 = Standard Cross Slot (Available in all pin styles except Z) 3 = Standard Single Slot w/Reverse Marking (Available only in J and Z pin style) 4 = Standard Cross Slot w/Reverse Marking (Available only in J pin style) GA4 = Custom Z Pin Style with Single Slot (Available only in Z pin style) GM5 = Custom Cross Slot with Extended Lead Frame (Available only in R pin style) J = J-Hook, Top Adjust G = Gull-Wing, Top Adjust H = Extended Leads, Top Adjust R = Gull-Wing, Reverse Adjust S = Side Adjust Z = Slanted Fixture, Side Adjust</p> <p>*Note: Only R offers GM5 option *Note: Only Z offers the GA4 option and does not offer Cross Slot option *Note: Only R offers GM5 option and does not offer Single Slot option</p>	100 Ohms to 2 Megohms	<p>E = 7" Reel J, G and R pin styles = 500 pcs. S and Z pin styles = 200 pcs.</p> <p>G = 13" Reel, J and G pin styles = 3000 pcs. G = 13" Reel, R pin style = 2500 pcs. G = 13" Reel, S and Z pin styles = 1000 pcs.</p> <p>Blank = 50 piece tube packaging - Only available packaging option for style H</p>

Part Number Examples

Model	Pin Style	Product Indicator	Resistance (Ohms)	Number of Pieces	Reel Size (Inches)
3314J-1-502E	J = J-Hook, Top Adjust	Single Slot (-1)	5000	500	7
3314G-1-100G	G = Gull-Wing, Top Adjust	Single Slot (-1)	10	3000	13
3314H-1-103	H = Extended Leads, Top Adjust	Single Slot (-1)	10000	50	Tube Only
3314R-1-205E	R = Gull-Wing, Reverse Adjust	Single Slot (-1)	2000000	500	7
3314S-1-203G	S = Side Adjust	Single Slot (-1)	20000	1000	13
3314Z-1-502G	Z = Slanted Fixture, Side Adjust	Single Slot (-1)	5000	1000	13
3314R-GM5-105G	R = Gull-Wing, Reverse Adjust	Cross Slot w/Extended Lead Frame (-GM5)	1000000	2500	13

www.bourns.com

BOURNS®

COPYRIGHT© 2024 • BOURNS, INC. • 02/24 • Mimeo • e/T2405
 "Bourns" and "Trimpot" are registered trademarks of Bourns, Inc. in the U.S. and other countries.

Americas: Tel: +1-951 781-5500
 Email: americus@bourns.com

EMEA: Tel: +36 88 520 390
 Email: eurocus@bourns.com

Asia-Pacific: Tel: +886-2 256 241 17
 Email: asiacus@bourns.com